

**Part No:** 5857-01012

**Swing Joints**

**Riser Assemblies**

**Desc:** 1 PVC SJR W/12 NIPPLE MPTXMPT MULTI-ELL

**MSRP:** 139.82

**Part Code:** 030

**Weight(lbs):** 2.346


**Weight(kg):** 1.064

**Weight(gm):** 1064

**Size:** 1"

**Color:** BLUE

**Material:** PVC

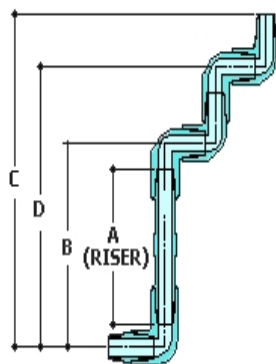

**Inlet** Mipt  
**Outlet** Mipt  
**Riser Type** Buttress Thread  
**Type** Multi - Ell  
**Riser Nipple Length** 12

**A** = 12

**B** = 13- 1/2

**C** = 19-19/32

**D** = 17- 3/16

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

