

**Part No:** 597-010-4AR

**Swing Joints**

**Adapter**

**Desc:** 1 PVC SWG JNT ADAPT BSPXMBT W/O-RINGS C

**MSRP:** 26.03

**Part Code:** 030

**Weight(lbs):** 0.13

**Weight(kg):** 0.059

**Weight(gm):** 59

**Size:** 1


**Color:** BLUE

**Material:** PVC

**Connection** BSP x MBT

**Type** Inlet Adapter

**Note** With O-Rings

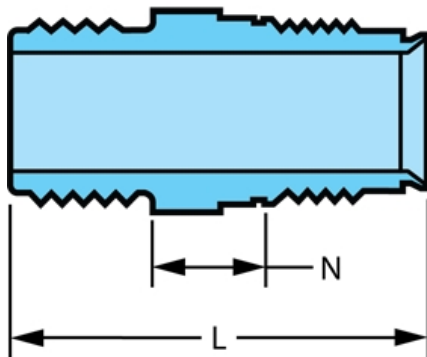

**L** = 3-1/4

**N** = 5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

