

Part No: 6562-007C

Valves

Diaphragm Check Valve

Desc: 3/4 CPVC DIAPHRAGM CHECK VALVE SOC

MSRP: 196.49

Part Code: 004

Weight(lbs): 0.313


Weight(kg): 0.142

Weight(gm): 142

Size: 3/4

Color: GRAY

Material: CPVC

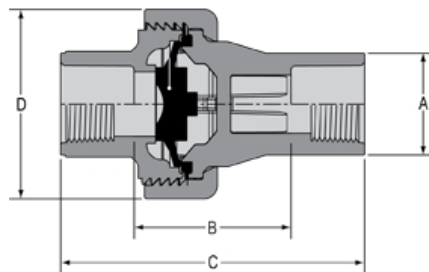

Type Diaphragm Check
Connection Socket
Diaphragm Material Santoprene™ Rubber
Pressure Rating 150 psi @ 73° F Full Flow (open)
 100 psi Back Pressure

A = 1- 7/16

B = 2- 1/8

C = 4- 1/8

D = 2-21/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

