

Part No: 7027L1-005

Valves

3-Way Full Port Ball Valve

Desc: 1/2 PVC TU IND 3WFP HOR L1 SPG EPDM

MSRP: 198.63

Part Code: 615

Weight(lbs): 0.772


Weight(kg): 0.35

Weight(gm): 350

Size: 1/2

Color: GRAY

Material: PVC

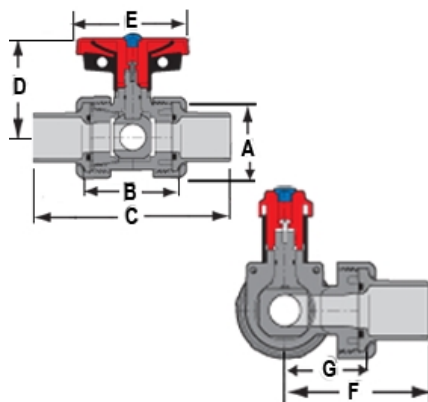

Type L - Port (Horizontal)
Connection Spigot
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

A = 2-1/8

B = 4-1/8

C = 5-7/8

D = 2-5/8

E = 2-13/16

F = 2-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

