

Part No: 7031L1-007CSR

Valves

3-Way Full Port Ball Valve

Desc: 3/4 CPVC TU IND 3WFP HOR L1 SRFPT FKM

MSRP: 350.56

Part Code: 617

Weight(lbs): 1.303


Weight(kg): 0.591

Weight(gm): 591

Size: 3/4

Color: GRAY

Material: CPVC

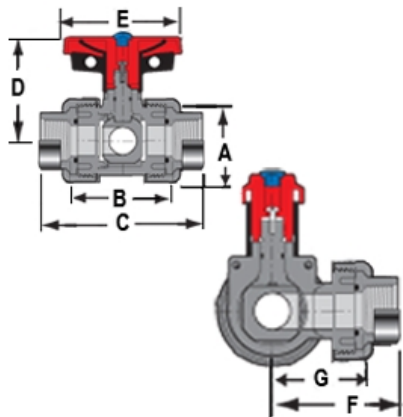

Type L - Port (Horizontal)
Connection SR Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

A = 2-9/16

B = 4-1/4

C = 5-3/4

D = 3

E = 3-3/8

F = 2-7/8

G = 2-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

