

Part No: 7031L1-015SR

Valves

3-Way Full Port Ball Valve

Desc: 1-1/2 PVC TU IND 3WFP HOR L1 SRFPT FKM

MSRP: 391.29

Part Code: 615

Weight(lbs): 3.792


Weight(kg): 1.72

Weight(gm): 1720

Size: 1-1/2

Color: GRAY

Material: PVC

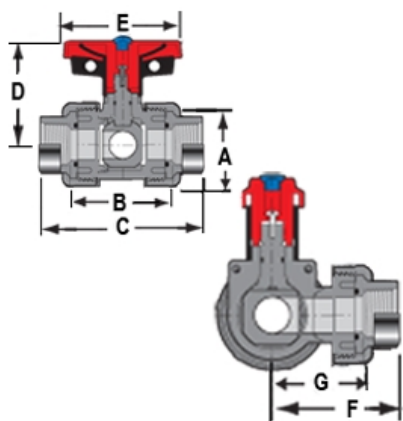

Type L - Port (Horizontal)
Connection SR Fipt
O-Ring FKM
Pressure Rating 235 psi @ 73° F

A = 4

B = 6-1/4

C = 8-1/8

D = 4-3/16

E = 4-3/16

F = 4-1/16

G = 3-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

