

**Part No:** 7032L1-020

**Valves**

**3-Way Full Port Ball Valve**

**Desc:** 2 PVC TU IND 3WFP HOR L1 SOC FKM

**MSRP:** 486.73

**Part Code:** 615

**Weight(lbs):** 5.569


**Weight(kg):** 2.526

**Weight(gm):** 2526

**Size:** 2

**Color:** GRAY

**Material:** PVC

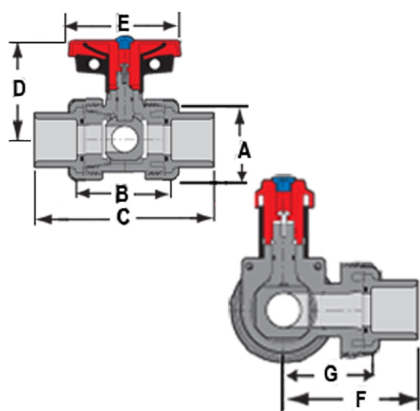

**Type** L - Port (Horizontal)  
**Connection** Socket  
**O-Ring** FKM  
**Pressure Rating** 235 psi @ 73° F

A = 4-5/8

B = 7-1/4

C = 10-1/4

D = 4-9/16

E = 5-1/8

F = 5-1/8

G = 3-5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

