

Part No: 7033L1-012C

Valves

3-Way Full Port Ball Valve

Desc: 1-1/4 CPVC TU IND 3WFP HOR L1 FLG FKM

MSRP: 1626.53

Part Code: 617

Weight(lbs): 4.414


Weight(kg): 2.002

Weight(gm): 2002

Size: 1-1/4

Color: GRAY

Material: CPVC

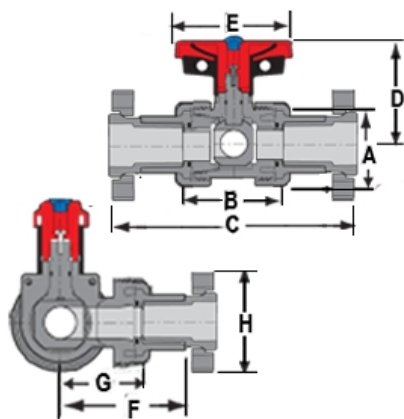

A = 3-9/16

H = 3-7/8

B = 5-5/8

C = 8-1/8

D = 3-3/4

E = 3-7/8

F = 4-1/16

G = 2-13/16

Type L - Port (Horizontal)
Connection Flanged
O-Ring FKM
Pressure Rating 150 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

