

Part No: 7033T1-007C

Valves

3-Way Full Port Ball Valve

Desc: 3/4 CPVC TU IND 3WFP HOR T1 FLG FKM

MSRP: 596.09

Part Code: 617

Weight(lbs): 2.196


Weight(kg): 0.996

Weight(gm): 996

Size: 3/4

Color: GRAY

Material: CPVC

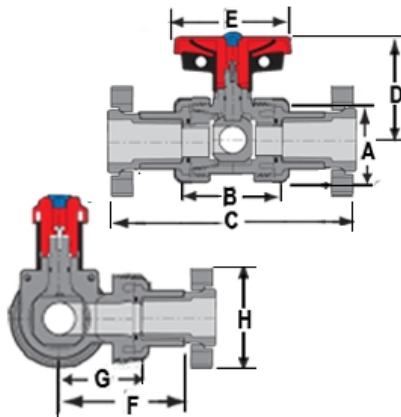

Type T - Port (Horizontal)
Connection Flanged
O-Ring FKM
Pressure Rating 150 psi @ 73° F

A = 2-9/16

B = 4-1/4

C = 6-1/4

D = 3

E = 3-3/8

F = 3-1/8

G = 2-1/8

H = 4-5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

