

Part No: 7121L3-007SR

Valves

3-Way Full Port Ball Valve

Desc: 3/4 PVC TU IND 3WFP VRT L3 SRFPT EPDM

MSRP: 377.76

Part Code: 615

Weight(lbs): 1.237


Weight(kg): 0.561

Weight(gm): 561

Size: 3/4

Color: GRAY

Material: PVC

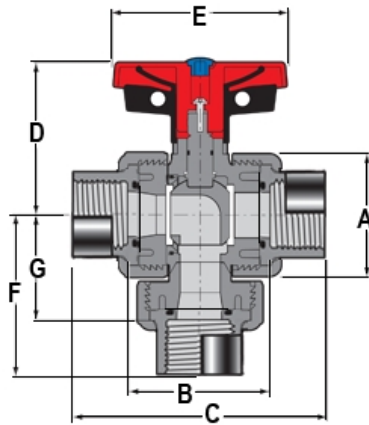

A = 2-9/16

B = 4-1/4

C = 5-3/4

D = 3

E = 3-3/8

F = 2-7/8

G = 2-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

