

Part No: 7121L3-010CSR

Valves

3-Way Full Port Ball Valve

Desc: 1 CPVC TU IND 3WFP VRT L3 SRFPT EPDM

MSRP: 647.88

Part Code: 617

Weight(lbs): 1.671


Weight(kg): 0.758

Weight(gm): 758

Size: 1

Color: GRAY

Material: CPVC

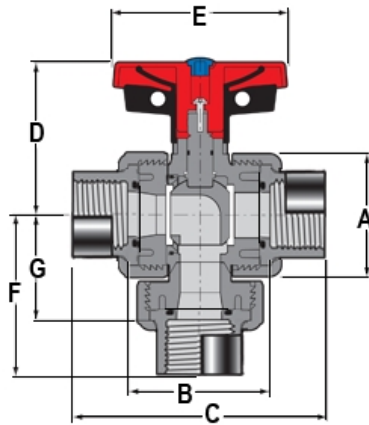

A = 2-7/8

B = 4-1/2

C = 6-3/8

D = 3-3/16

E = 3-7/16

F = 3-3/16

G = 2-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

