

Part No: 7122L1-010

Valves

3-Way Full Port Ball Valve

Desc: 1 PVC TU IND 3WFP VRT L1 SOC EPDM

MSRP: 283.53

Part Code: 615

Weight(lbs): 1.554


Weight(kg): 0.705

Weight(gm): 705

Size: 1

Color: GRAY

Material: PVC Gray

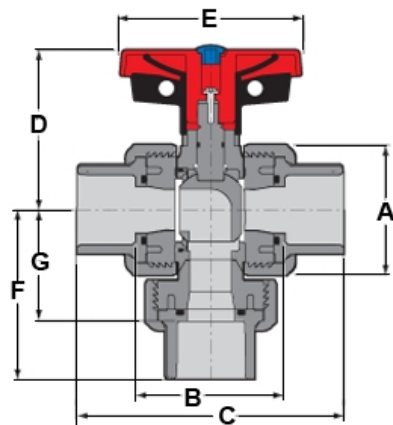

E = 3-7/16

F = 3-3/8

G = 2-1/4

A = 2-7/8

B = 4-1/2

C = 6-13/16

D = 3-3/16

Connection Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

Type Single L - Port (Vertical)

Connection Socket

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

