

Part No: 7122L2-015C

Valves

3-Way Full Port Ball Valve

Desc: 1-1/2 CPVC TU IND 3WFP VRT L2 SOC EPDM

MSRP: 787.27

Part Code: 617

Weight(lbs): 3.876


Weight(kg): 1.758

Weight(gm): 1758

Size: 1-1/2

Color: GRAY

Material: CPVC

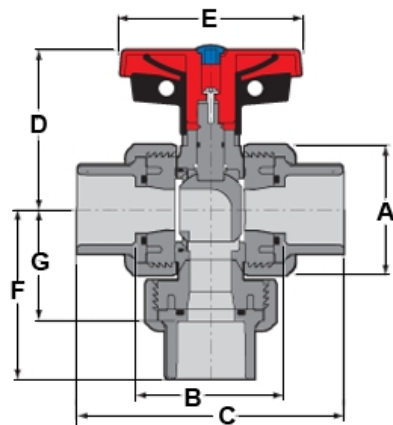

A = 4

B = 6-1/4

C = 9

D = 4-3/16

E = 4-3/16

F = 4-1/2

G = 3-1/8

Type Double L - Port (Vertical)
Connection Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

