

Part No: 7122L3-005C

Valves

3-Way Full Port Ball Valve

Desc: 1/2 CPVC TU IND 3WFP VRT L3 SOC EPDM

MSRP: 525.11

Part Code: 617

Weight(lbs): 0.805


Weight(kg): 0.365

Weight(gm): 365

Size: 1/2

Color: GRAY

Material: CPVC

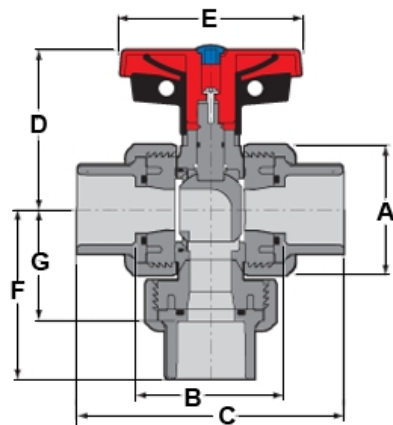

F = 2-11/16

G = 1-13/16

A = 2-1/8

B = 3-5/8

C = 5-3/8

D = 2-5/8

E = 2-13/16

Type Triple L - Port (Vertical)
Connection Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

