

Part No: 7122T1-005

Valves

3-Way Full Port Ball Valve

Desc: 1/2 PVC TU IND 3WFP VRT T1 SOC EPDM

MSRP: 198.63

Part Code: 615

Weight(lbs): 0.754


Weight(kg): 0.342

Weight(gm): 342

Size: 1/2

Color: GRAY

Material: PVC

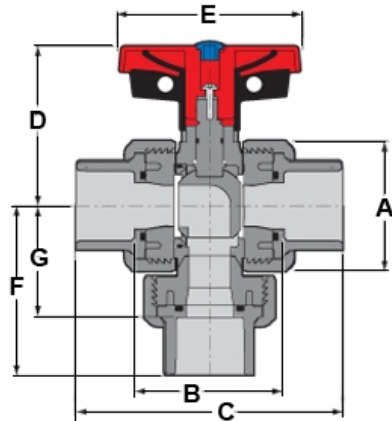

Type T - Port (Vertical)
Connection Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

A = 2-1/8 B = 3-5/8 C = 5-3/8 D = 2-5/8 E = 2-13/16
 F = 2-11/16 G = 1-13/16

Injection Molded Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch
- L** = Overall length of fittings; ± 1/16 inch.
- M** = Outside diameter of socket/thread hub; ± 1/16 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.
- W** = Height of cap; ± 1/16 inch

Typical Molded Dimension References

