

**Part No:** 7122T1-020

**Valves**

**3-Way Full Port Ball Valve**

**Desc:** 2 PVC TU IND 3WFP VRT T1 SOC EPDM

**MSRP:** 419.22

**Part Code:** 615

**Weight(lbs):** 5.494


**Weight(kg):** 2.492

**Weight(gm):** 2492

**Size:** 2

**Color:** GRAY

**Material:** PVC

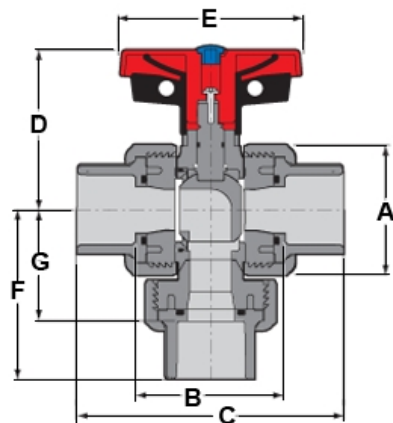

**A** = 4-5/8

**B** = 7-1/4

**C** = 10-1/4

**D** = 4-9/16

**E** = 5-1/8

**F** = 5-1/8

**G** = 3-5/8

**Type** T - Port (Vertical)  
**Connection** Socket  
**O-Ring** EPDM  
**Pressure Rating** 235 psi @ 73° F

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

