

Part No: 7132L3-010C

Valves

3-Way Full Port Ball Valve

Desc: 1 CPVC TU IND 3WFP VRT L3 SOC FKM

MSRP: 679.89

Part Code: 617

Weight(lbs): 1.651


Weight(kg): 0.749

Weight(gm): 749

Size: 1

Color: GRAY

Material: CPVC

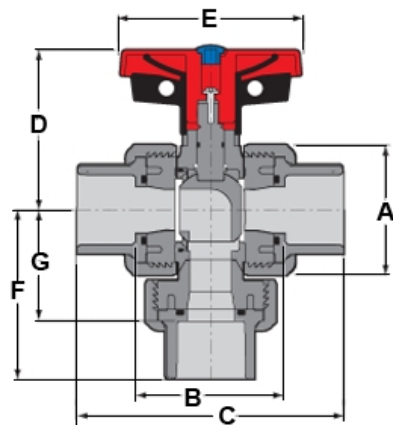

A = 2-7/8

B = 4-1/2

C = 6-3/4

D = 3-3/16

E = 3-7/16

F = 3-3/8

G = 2-1/4

Type Triple L - Port (Vertical)
Connection Socket
O-Ring FKM
Pressure Rating 235 psi @ 73° F

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

