

Part No: 721301G-100C

Valves

Butterfly Valve

Desc: 10 CPVC LUG INS BFV BUNA L/HANDLE SS/LUG

MSRP: 6977.54

Part Code: 252

Weight(lbs): 28.116

Weight(kg): 12.753

Weight(gm): 12753

Size: 10


Color: GRAY

Material: CPVC

Design Lug Insert (SS)

Handle Valve Only

O-Ring Buna-N

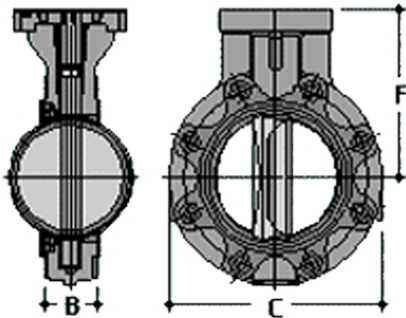

No of Bolts = 12

Bolt Circle Dia. = 14-1/4

Bolt Size = 7/8

B = 3-1/4

C = 16

F = 11

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

