

Part No: 721301L-040

Valves

Butterfly Valve

Desc: 4 PVC TL BFV BUNA L/HANDLE S/S LUG

MSRP: 2386.56

Part Code: 250

Weight(lbs): 9.815


Weight(kg): 4.452

Weight(gm): 4452

Size: 4"

Color: GRAY

Material: PVC

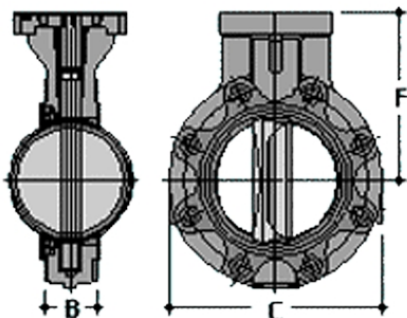

Design True Lug (SS)
Handle Valve Only
O-Ring Buna-N
Pressure Rating 150 psi @ 73° F

B = 3

C = 9

F = 6- 1/4

No of Bolts = 8

Bolt Circle Dia. = 7- 1/2

Bolt Size = 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

