

Part No: 721311L-015C

Valves

Butterfly Valve

Desc: 1-1/2 CPVC TL BFV BUNA W/HANDLE SS/LUG

MSRP: 1668.68

Part Code: 252

Weight(lbs): 3.384

Weight(kg): 1.535

Weight(gm): 1535

Size: 1-1/2"


Color: GRAY

Material: CPVC

Design True Lug (SS)

Handle Lever Handle

O-Ring Buna-N

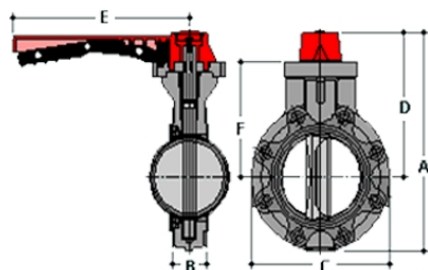

A = 8- 5/32

B = 2- 1/4

C = 5

No of Bolts = 4

Bolt Circle Dia. = 3- 7/8

Bolt Size = 7/16

D = 5-19/32

E = 9- 3/32

F = 4- 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

