

Part No: 722301-060C

Valves

Butterfly Valve

Desc: 6 CPVC BUTTERFLY VALVE EPDM L/HANDLE

MSRP: 1236.6

Part Code: 252

Weight(lbs): 11.94

Weight(kg): 5.416

Weight(gm): 5416

Size: 6"


Color: GRAY

Material: CPVC

Design Standard

Handle Valve Only

O-Ring EPDM

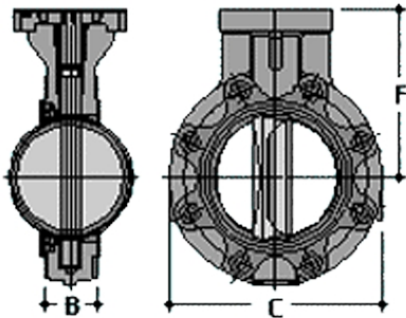

B = 2- 3/4

C = 11- 1/16

F = 8- 5/8

Bolt Size = 3/4

No of Bolts = 8

Bolt = 9- 1/2
Circle
Dia.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

