

**Part No:** 752301-040

**Valves**

**Butterfly Valve**

**Desc:** 4 PVC WAFER BUTTERFLY VLV EPDM L/HANDLE

**MSRP:** 558.01

**Part Code:** 250

**Weight(lbs):** 3.126

**Weight(kg):** 1.418

**Weight(gm):** 1418

**Size:** 4


**Color:** GRAY

**Material:** PVC

**Design** Wafer

**Handle** Valve Only

**O-Ring** EPDM

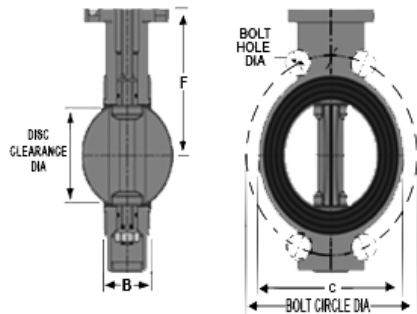

**B** = 2- 1/16

**C** = 6- 1/4

**F** = 5- 3/8

**No of Bolts** = 8

**Bolt Circle Dia.** = 7- 5/16

**Bolt Size** = 5/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

