

Part No: 752301-100C

Valves

Butterfly Valve

Desc: 10 CPVC WAFER BFYVLV EPDM L/GEAR OPTR

MSRP: 4282.98

Part Code: 252

Weight(lbs): 20.514

Weight(kg): 9.305

Weight(gm): 9305

Size: 10


Color: GRAY

Material: CPVC

Design Wafer

Handle Valve Only

O-Ring EPDM

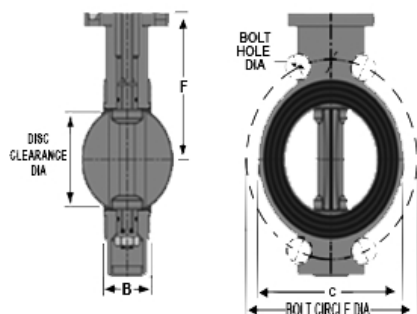

B = 2-9/16

C = 12-7/8

F = 10-11/16

No of Bolts = 12

Bolt Circle Dia. = 14-1/4

Bolt Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

