

Part No: 753301-040C

Valves

Butterfly Valve

Desc: 4 CPVC WAFER BTTERFLY VALVE FKM L/HANDLE

MSRP: 1741.91

Part Code: 252

Weight(lbs): 3.243

Weight(kg): 1.471

Weight(gm): 1471

Size: 4


Color: GRAY

Material: CPVC

Design Wafer

Handle Valve Only

O-Ring FKM

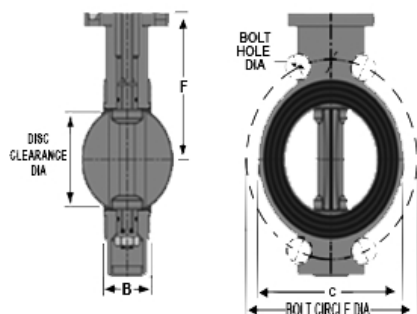

B = 2- 1/16

C = 6- 1/4

F = 5- 3/8

No of Bolts = 8

Bolt Circle Dia. = 7-1/2

Bolt Size = 5/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

