

Part No: 753301-120

Valves

Butterfly Valve

Desc: 12 PVC WAFER BFYVLV FKM L/GEAR OPTR

MSRP: 9312.38

Part Code: 250

Weight(lbs): 24.515

Weight(kg): 11.12

Weight(gm): 11120

Size: 12


Color: GRAY

Material: PVC

Design Wafer

Handle Valve Only

O-Ring FKM

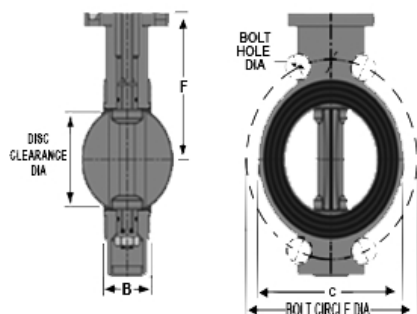

Bolt Size = 7/8

B = 3-1/16

C = 15-9/16

F = 11-11/16

No of Bolts = 12

Bolt Circle Dia. = 17

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

