

Part No: 801-666

Schedule 80 PVC & CPVC

Tee

Desc: 12X6 PVC RED TEE SOC SCH80

MSRP: 4628.2

Part Code: 081

Weight(lbs): 46.462

Weight(kg): 21.075

Weight(gm): 21075


Size: 12 X 6

Color: GRAY

Material: PVC

Connection Socket x Socket x Socket

Type Reduction

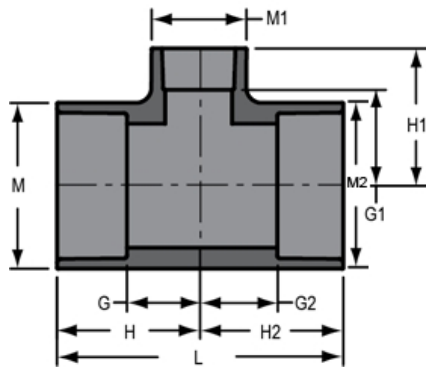

G = 4-7/8	G1 = 8-1/2	G2 = 4-7/8	M2 = 14- 9/32	H = 11-15/32
H1 = 11-1/2	H2 = 11-15/32	L = 22-29/32	M = 14-9/32	M1 = 9-23/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

