

Part No: 801-670C

Schedule 80 PVC & CPVC

Tee

Desc: 12X10 CPVC RED TEE SOC SCH80

MSRP: 8362.49

Part Code: 091

Weight(lbs): 69.82

Weight(kg): 31.67

Weight(gm): 31670


Size: 12"X12"X10"

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket

Type Reduction

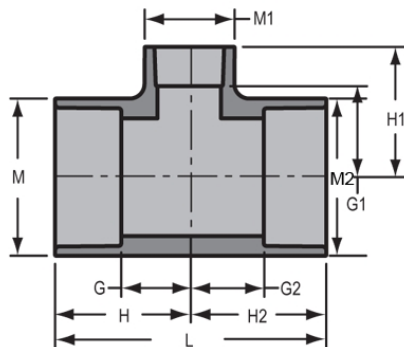

G = 6- 15/16

G1 = 8-13/32

G2 = 6- 15/16

H = 12-15/16

H1 = 13-13/32

H2 = 12-15/16

L = 25-7/8

M = 14-3/16

M1 = 14-3/16

M2 = 14-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

