

Part No: 801-700

Schedule 80 PVC & CPVC

Tee

Desc: 14X10 PVC RED TEE SOC SCH80

MSRP: 4183

Part Code: 082

Weight(lbs): 72.962

Weight(kg): 33.095

Weight(gm): 33095


Size: 14 X 10

Color: GRAY

Material: PVC

Connection Socket x Socket x Socket

Type Reduction

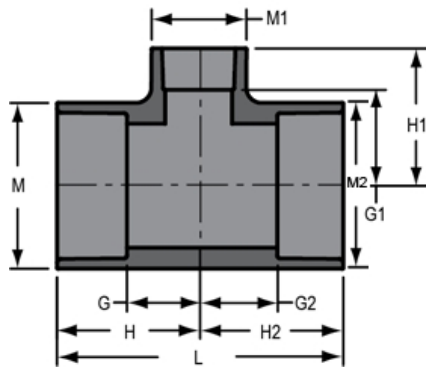

H1 = 13-7/8

H2 = 14-1/32

L = 28-1/16

M = 15-21/32

M1 = 14-1/4

M2 = 15-21/32

G = 7-1/32

G1 = 8-7/8

G2 = 7-1/32

H = 14-1/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

