

Part No: 801-814F

Fabricated Fittings

Tees

Desc: 20X4 PVC RED TEE SOC SCH80

MSRP: 5791.71

Part Code: 083

Weight(lbs): 123.28

Weight(kg): 55.919

Weight(gm): 55919

Size: 20"X20"X4"


Color: GRAY

Material: PVC

Schedule Schedule 80

Connection Socket X Socket X Socket

Type Reduction

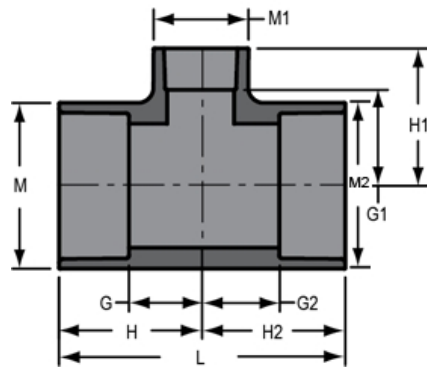

G = 7-11/16

G1 = 12- 7/8

G2 = 7-11/16

H = 17-11/16

H1 = 15- 1/8

H2 = 17-11/16

M2 = 22- 1/16

L = 35- 3/8

M = 22- 1/16

M1 = 5- 3/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

