

Part No: 801-822CF

Fabricated Fittings

Tees

Desc: 20X12 CPVC RED TEE SOC SCH80

MSRP: 25759.57

Part Code: 097

Weight(lbs): 199.75

Weight(kg): 90.605

Weight(gm): 90605

Size: 20"X20"X12"


Color: GRAY

Material: CPVC

Schedule Schedule 80

Connection Socket X Socket X Socket

Type Reduction

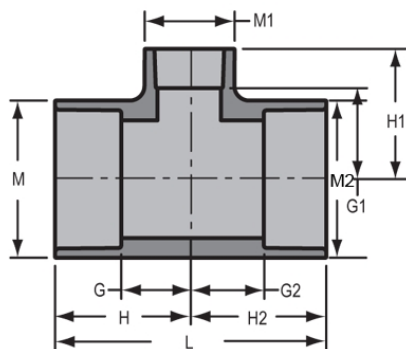

G = 11- 7/8	G1 = 14- 1/8	G2 = 11- 7/8	H = 21- 7/8	H1 = 20- 3/8
H2 = 21- 7/8	L = 43- 3/4	M = 22- 1/16	M1 = 14- 1/8	M2 = 22- 1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

