

Part No: 801-824CF

Fabricated Fittings

Tees

Desc: 20X14 CPVC RED TEE SOC SCH80

MSRP: 28698.58

Part Code: 097

Weight(lbs): 191.121

Weight(kg): 86.691

Weight(gm): 86691

Size: 20"X20"X14"


Color: GRAY

Material: CPVC

Schedule Schedule 80

Connection Socket X Socket X Socket

Type Reduction

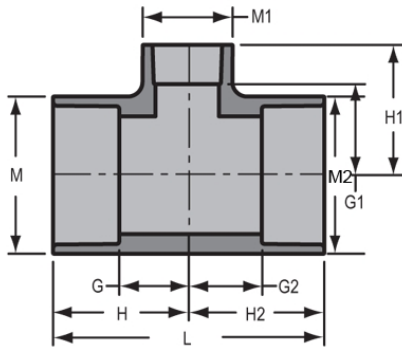

G = 12- 7/8

G1 = 14- 1/2

M2 = 22- 1/16

M = 22- 1/16

M1 = 15- 1/2

G2 = 12- 7/8

H = 22- 7/8

H1 = 21- 1/2

H2 = 22- 7/8

L = 45- 3/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

