

Part No: 801-906CF

Fabricated Fittings

Tees

Desc: 24X6 CPVC RED TEE SOC SCH80

MSRP: 24586.81

Part Code: 097

Weight(lbs): 253.682

Weight(kg): 115.068

Weight(gm): 115068

Size: 24"X24"X6"


Color: GRAY

Material: CPVC

Schedule Schedule 80

Connection Socket X Socket X Socket

Type Reduction

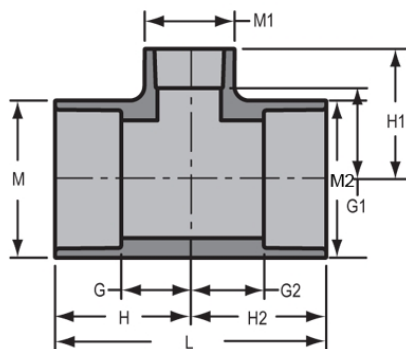

G = 9- 1/4	G1 = 15- 1/16	G2 = 9- 1/4	H = 21- 1/4	H1 = 18- 5/16
H2 = 21- 1/4	L = 42- 1/2	M = 26- 7/16	M1 = 7- 1/2	M2 = 26- 7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

