

Part No: 802-101CBR

Schedule 80 PVC & CPVC

Tee

Desc: 3/4X1/2 CPVC RED TEE SOCXBRFPT SCH80

MSRP: 121.53

Part Code: 096

Weight(lbs): 0.192

Weight(kg): 0.087

Weight(gm): 87


Size: 3/4"X3/4"X1/2"

Color: GRAY

Material: CPVC

Connection Socket x Socket x Brass Fipt

Type Reduction

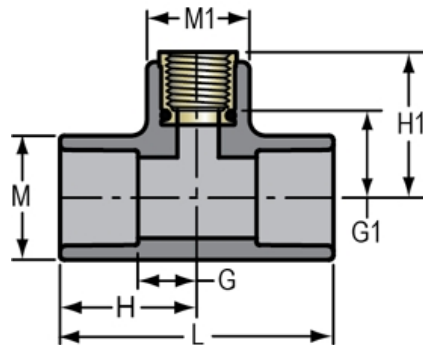

G = 7/16

G1 = 1- 1/32

H = 1- 7/16

H1 = 1- 5/8

L = 2-29/32

M = 1-13/32

M1 = 1- 3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

