

Part No: 803-113CSR

Schedule 80 PVC & CPVC

Tee

Desc: 1X1/4X1 CPVC INSTRUMENT PROBE FITTING

MSRP: 82.46

Part Code: 096

Weight(lbs): 0.395

Weight(kg): 0.179

Weight(gm): 179


Size: 1 X 1/4 X 1

Color: GRAY

Material: CPVC

Connection Socket x SR Fipt x Socket

Type Reduction

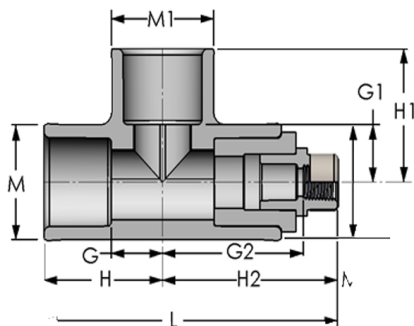

G = 7/8

G1 = 7/8

G2 = 2-3/8

H = 2

H1 = 2

H2 = 2-15/16

L = 4-15/16

M = 1-3/4

M1 = 1-3/4

M2 = 1-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

