

Part No: 8057-040BL

Low Extractable

Union

Desc: 4 PVC LE UNION 2000 SOC FKM

MSRP: 291.14

Part Code: 065

Weight(lbs): 3.759

Weight(kg): 1.705

Weight(gm): 1705

Size: 4"


Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type Union

O-Ring FKM

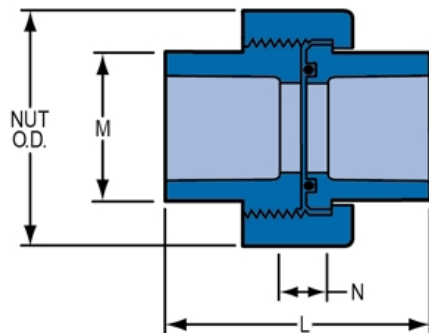

L = 5-3/16

M = 5- 1/4

N = 21/32

NUT = 7- 3/4
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

