

Part No: 806-005LSCF

Fabricated Fittings

Elbow

Desc: 1/2 CPVC LONG SWEEP 90 ELL SOC SCH80 FAB

MSRP: 91.97

Part Code: 097

Weight(lbs): 0.152

Weight(kg): 0.069

Weight(gm): 69

Size: 1/2"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 90 Degree

Connection Long Sweep

Type Standard

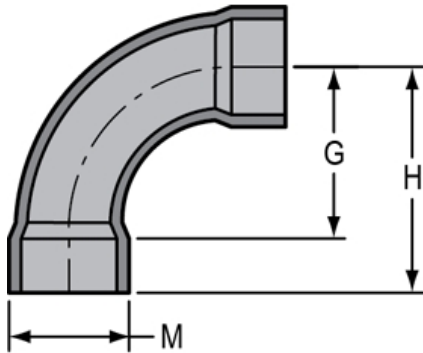

G = 1- 7/8

H = 2- 3/4

M = 1- 1/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

