

Part No: 806-007LSCF

Fabricated Fittings

Elbow

Desc: 3/4 CPVC LONG SWEEP 90 ELL SOC SCH80 FAB

MSRP: 103.03

Part Code: 097

Weight(lbs): 0.262

Weight(kg): 0.119

Weight(gm): 119

Size: 3/4"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 90 Degree

Connection Long Sweep

Type Standard

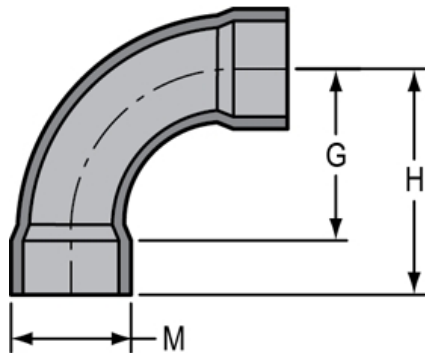

$$G = 2 - 7/16$$

$$H = 3 - 7/16$$

$$M = 1 - 7/16$$

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

