

Part No: 806-007S

Schedule 80 PVC & CPVC

Elbow

Desc: 3/4 PVC SWEEP ELL SOC SCH80

MSRP: 17.91

Part Code: 080

Weight(lbs): 0.198

Weight(kg): 0.09

Weight(gm): 90

Size: 3/4"


Color: GRAY

Material: PVC

Connection Sweep - Short

Angle 90°

Type Standard

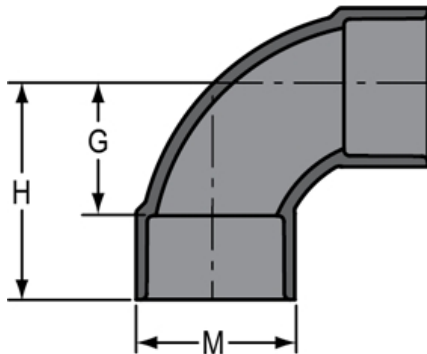

G = 1-1/16

H = 2-1/16

M = 1-13/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

