

Part No: 806-007SBL

Low Extractable

Elbow

Desc: 3/4 PVC LE SWEEP ELL SOC SCH80

MSRP: 12.96

Part Code: 065

Weight(lbs): 0.117

Weight(kg): 0.053

Weight(gm): 53


Size: 3/4"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 90° Sweep Elbow

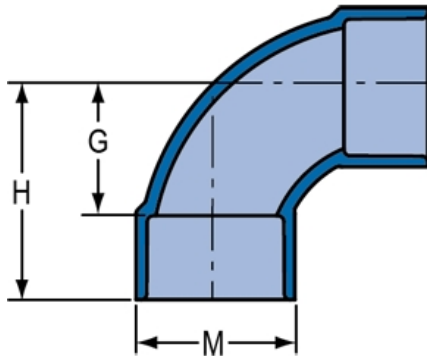

G = 1-1/16

H = 1-1/16

M = 1-13/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

