

Part No: 806-010S

Schedule 80 PVC & CPVC

Elbow

Desc: 1 PVC SWEEP ELL SOC SCH80

MSRP: 28.86

Part Code: 080

Weight(lbs): 0.22

Weight(kg): 0.1

Weight(gm): 100

Size: 1"


Color: GRAY

Material: PVC

Connection Sweep - Short

Angle 90°

Type Standard

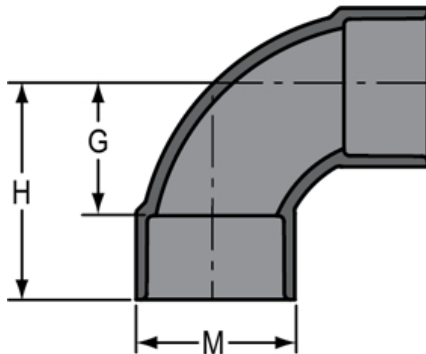

G = 1- 5/16

H = 2- 7/16

M = 1-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

