

Part No: 806-012SBL

Low Extractable

Elbow

Desc: 1-1/4 PVC LE SWEEP ELL SOC SCH80

MSRP: 40.92

Part Code: 065

Weight(lbs): 0.28

Weight(kg): 0.127

Weight(gm): 127


Size: 1-1/4"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 90° Sweep Elbow

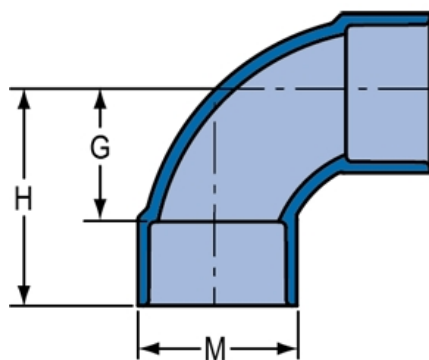

$$G = 1 - 9/16$$

$$H = 2 - 27/32$$

$$M = 2 - 3/32$$

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

