

Part No: 806-015BL

Low Extractable

Elbow

Desc: 1-1/2 PVC LE 90 ELL SOC SCH80

MSRP: 42.38

Part Code: 065

Weight(lbs): 0.381

Weight(kg): 0.173

Weight(gm): 173


Size: 1-1/2"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 90° Elbow

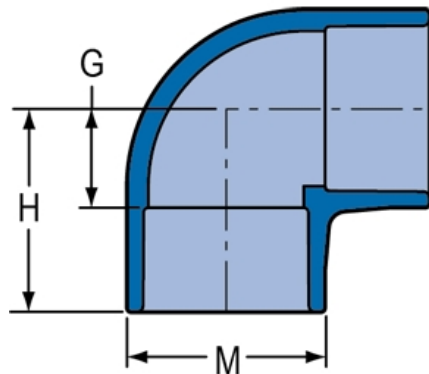

G = 1-5/32

H = 2-9/16

M = 2-11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

