

Part No: 806-015LSCF

Fabricated Fittings

Elbow

Desc: 1 1/2 CPVC LONG SWEEP 90 ELL SOC SCH80

MSRP: 136.29

Part Code: 097

Weight(lbs): 0.657

Weight(kg): 0.298

Weight(gm): 298

Size: 1-1/2"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 90 Degree

Connection Long Sweep

Type Standard

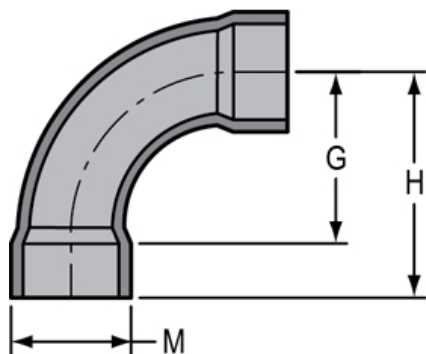

G = 4- 1/8

H = 5- 1/2

M = 2- 5/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

