

Part No: 806-040BL

Low Extractable

Elbow

Desc: 4 PVC LE 90 ELL SOC SCH80

MSRP: 338.86

Part Code: 065

Weight(lbs): 2.804

Weight(kg): 1.272

Weight(gm): 1272


Size: 4"

Color: BLUE

Material: PVC LE

Connection Socket x Socket

Type 90° Elbow

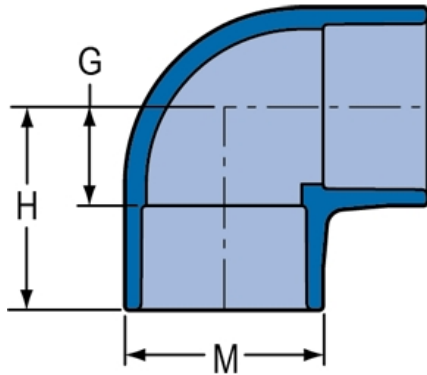

G = 2-19/32

H = 4-27/32

M = 5- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

