

Part No: 806-050CF

Fabricated Fittings

Elbow

Desc: 5 CPVC 90 ELL SOC SCH80 FAB

MSRP: 706.86

Part Code: 097

Weight(lbs): 7.408

Weight(kg): 3.36

Weight(gm): 3360

Size: 5"

Color: GRAY


Material: CPVC

Schedule SCH 80

Angle 90 Degree

Connection Socket X Socket

Type Standard

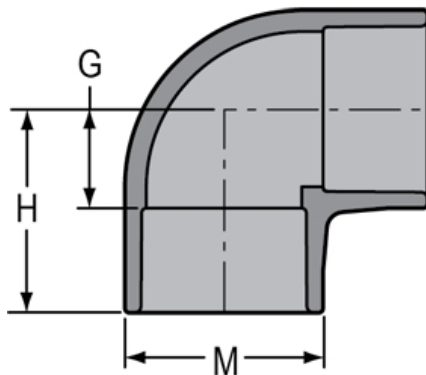

G = 6- 9/16

H = 9- 9/16

M = 6- 5/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

