

Part No: 806-140

Schedule 80 PVC & CPVC

Elbow

Desc: 14 PVC 90 ELBOW SOC SCH80

MSRP: 4063.18

Part Code: 082

Weight(lbs): 54.256

Weight(kg): 24.61

Weight(gm): 24610

Size: 14


Color: GRAY

Material: PVC

Connection Socket x Socket

Angle 90°

Type Standard

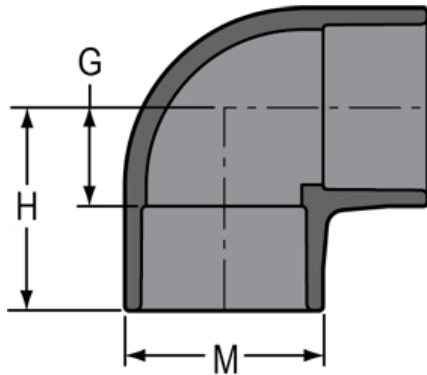

G = 7- 1/2

H = 14- 1/2

M = 15-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

