

Part No: 809-100C

Schedule 80 PVC & CPVC

Elbow

Desc: 10 CPVC 90 ST ELL SPIGOTXSOC SCH80

MSRP: 4926.66

Part Code: 091

Weight(lbs): 34.987


Weight(kg): 15.87

Weight(gm): 15870

Size: 10"

Color: GRAY

Material: CPVC

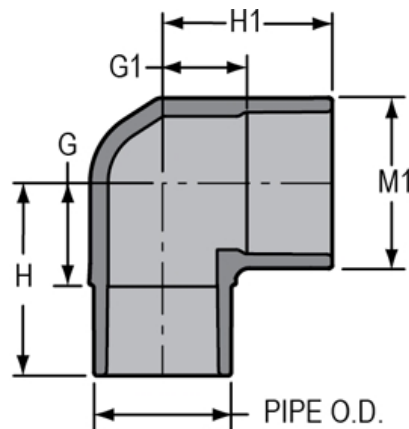

Connection Spigot x Socket

Angle 90°

Type Standard

G = 8-7/8

G1 = 5-7/8

H = 13-7/8

H1 = 10-7/8

M1 = 12- 1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

