

**Part No:** 8099-060C

**Schedule 80 PVC & CPVC**

**Union**

**Desc:** 6 CPVC UNION 2000 SOCXFPT EPDM

**MSRP:** 1108.78

**Part Code:** 090

**Weight(lbs):** 11.779

**Weight(kg):** 5.343

**Weight(gm):** 5343


**Size:** 6"

**Color:** GRAY

**Material:** CPVC

**Connection** Socket x Fipt (2000)

**O-Ring** EPDM

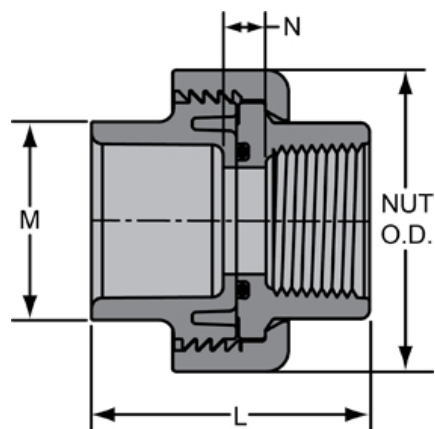

**L** = 6-27/32

**M** = 7-21/32

**N** = 1-17/32

**NUT** = 11- 5/8  
**O.D.**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

