

Part No: 811-007CF

Fabricated Fittings

Elbow

Desc: 3/4 CPVC 11-1/4 ELL SOC SCH80

MSRP: 56.2

Part Code: 097

Weight(lbs): 0.088


Weight(kg): 0.04

Weight(gm): 40

Size: 3/4

Color: GRAY

Material: CPVC

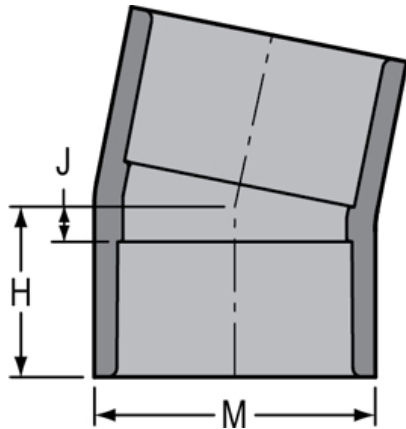

H = 1-5/16

J = 5/16

M = 1-3/8

Schedule SCH 80

Angle 11-1/4 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

