

Part No: 811-015C

Schedule 80 PVC & CPVC

Elbow

Desc: 1-1/2 CPVC 11-1/4 ELL SOC SCH80

MSRP: 62.01

Part Code: 090

Weight(lbs): 0.254

Weight(kg): 0.115

Weight(gm): 115

Size: 1-1/2"


Color: GRAY

Material: CPVC

Connection Socket x Socket

Angle 11-1/4°

Type Standard

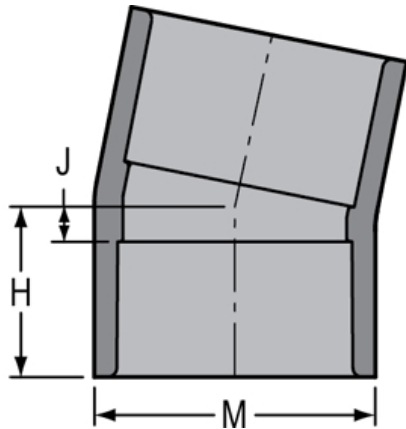

H = 1-19/32

J = 7/32

M = 2-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

